




**SKF USA, Inc.**  
 890 Forty Foot Rd  
 Lansdale, PA  
**Phone:** 1-267-436-6000 • **Fax:** 1-267-436-6001  
**Email:** [AskEngineeringHotline@skf.com](mailto:AskEngineeringHotline@skf.com)  
**Website:** <http://www.skf.com/us/products/mrc/index.html>

## Item # 88503, Speciality Bearings Felt Seal Replacement Bearings

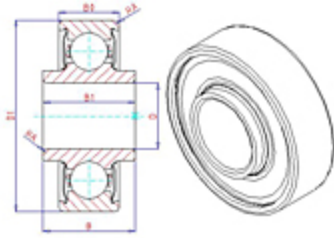

### Specifications

<b>Old MRC Bearing Number</b>	203FFS
<b>Bore d</b>	17.000 mm
<b>Outside Diameter D1</b>	40.0000 mm
<b>Width - Outer Ring B0</b>	12.0 mm
<b>Width - Inner Ring B1</b>	16.60 mm
<b>Width - Overall B</b>	16.6 mm
<b>Fillet Radius ra</b>	0.64 mm
<b>Basic Radial Load Rating-Dynamic DC</b>	9560 N
<b>Basic Radial Load Rating-Static SCO</b>	4800 N
<b>Speed Rating-Single and Double Sealed Grease SDG</b>	12000 rpm
<b>Basic Interchange BCA</b>	88503
<b>Basic Interchange FAF</b>	203KLL2
<b>Basic Interchange NDH</b>	88503
<b>Accessories</b>	88000 Two Seals